


EA01641T/04/A2/01.25-00
71705956
2025.05.08

TA20B

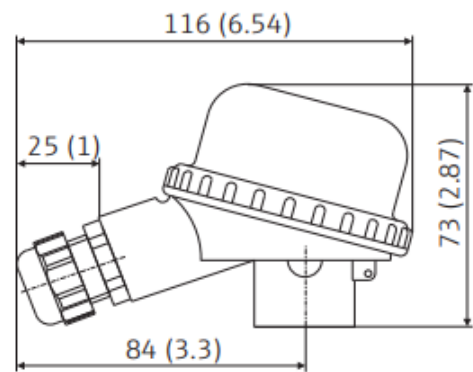

- Schutzart: IP65
- Temperatur: -40 °C (-40 °F)...+80 °C (+176 °F), ohne Kabelverschraubung
- Material: Polyamid (PA)
- Kabeleingang: M20x1,5
- Kopf- und Kappenfarbe: schwarz
- Gewicht: 80 g (2,82 oz)
- 3-A® gekennzeichnet

- Degree of protection: IP65
- Temperature: -40 °C (-40 °F)...+80 °C (+176 °F), w/o cable gland
- Material: polyamide (PA)
- Cable entry: M20x1.5
- Head and cap color: black
- Weight: 80 g (2.82 oz)
- 3-A® marked