

XPC0017-F+M1: Kit CPA842 Weld-in socket G1¼" DN25 standard straight, 1.4435/316L



Kit Content	Pcs.	Pos.
Weld-in socket straight, l = 30 mm	1	a
Cleaning tissue	1	b

XPC0017-F+M2: Kit CPA842 Weld-in socket G1¼" DN25 standard oblique, 1.4435/316L



Kit Content	Pcs.	Pos.
Weld-in socket oblique, l = 39 mm, 15°	1	a
Cleaning tissue	1	b

XPC0017-F+M3: Kit CPA842 Weld-in socket G1¼" DN25 B.Braun straight, 1.4435/316L



Kit Content	Pcs.	Pos.
Weld-in socket straight B.Braun, l = 50 mm	1	a
Cleaning tissue	1	b

XPC0017-F+M4: Kit CPA842 Weld-in socket G1¼" DN25 B.Braun oblique, 1.4435/316L



Kit Content	Pcs.	Pos.
Weld-in socket oblique B.Braun, l = 59 mm, 15°	1	a
Cleaning tissue	1	b

XPC0017-F+M5: Kit blind plug G1¼" DN25 standard




Kit Content	Pcs.	Pos.
Blind plug G1¼" DN25 standard, l = 30 mm, 316L, FKM	1	a
Cleaning tissue	1	b

XPC0017-F+M6: Kit blind plug G1¼" DN25 B.Braun



Kit Content	Pcs.	Pos.
Blind plug G1¼" DN25 B.Braun, l = 50 mm, 316L, FKM	1	a
Cleaning tissue	1	b

XPC0017-F+PQ: Kit dummy sensor 120 mm

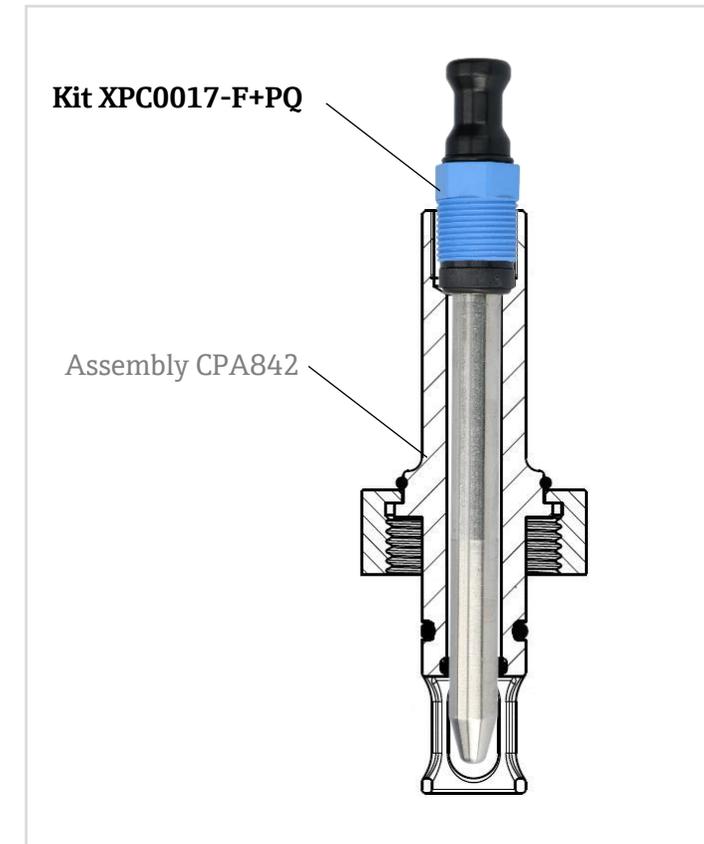



Kit Content	Pcs.	Pos.
Dummy sensor 120 mm, 316L, Ra = 0.38	1	a
Cleaning tissue	1	b

XPC0017-F+P1: Kit CPA842 snap rings




Kit Content	Pcs.	Pos.
Snap ring	10	a

XPC0017-F+Q1: Kit CPA842 10 pcs. wetted sealings EPDM (all process connections)

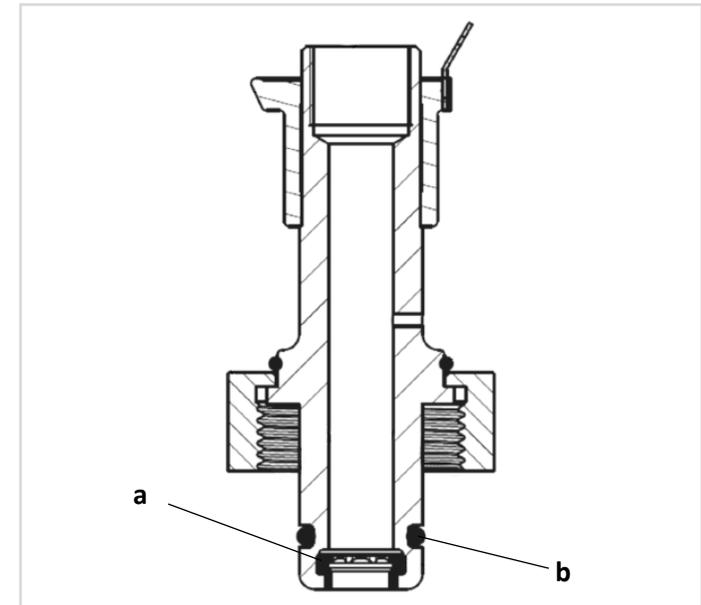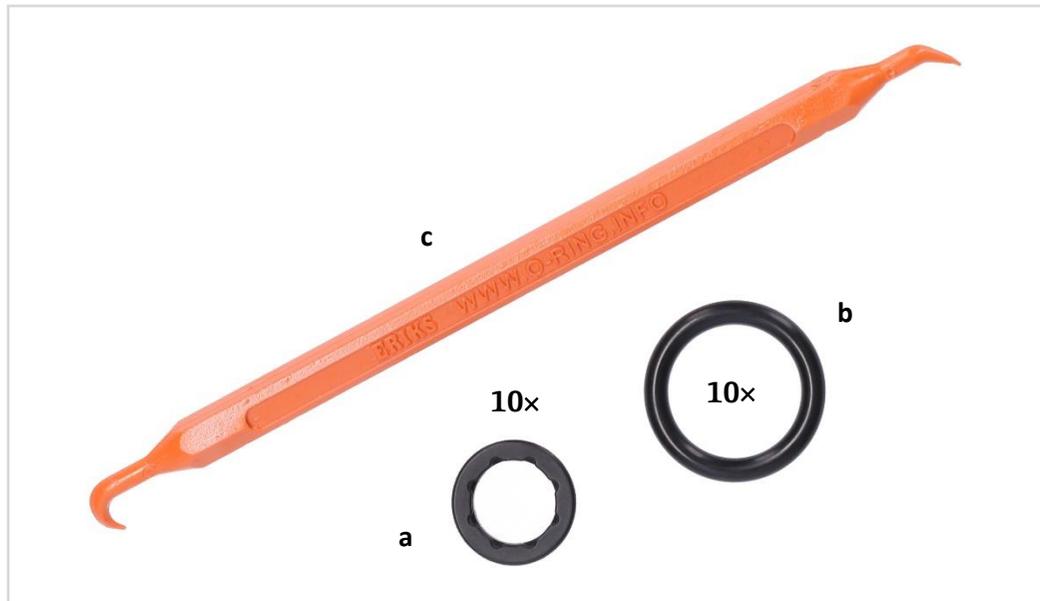

Kit Content	Pcs.	Pos.
Molded gasket OD 17.8 EPDM	10	a
O-ring OD 18.66 W 3.53 EPDM (only needed for DN25/G1¼")	10	b
O-ring picker	1	c

XPC0017-F+RR: O-ring dismantling tool, 5 pieces

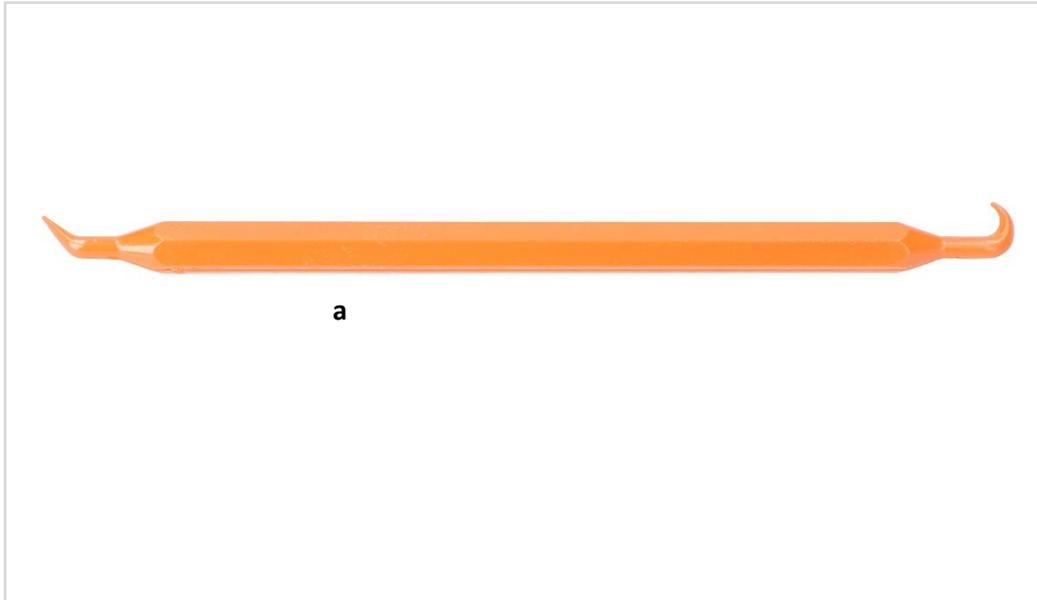



Kit Content	Pcs.	Pos.
O-ring picker	5	a

XPC0017-F+RS: Sensor mounting open end wrench, 2 pieces



Kit Content	Pcs.	Pos.
Mounting tool open end wrench AF17-AF19	2	a

XPC0017-F+RT: Kit CPA842 wetted sealings silicone (VMQ) (all process connections)

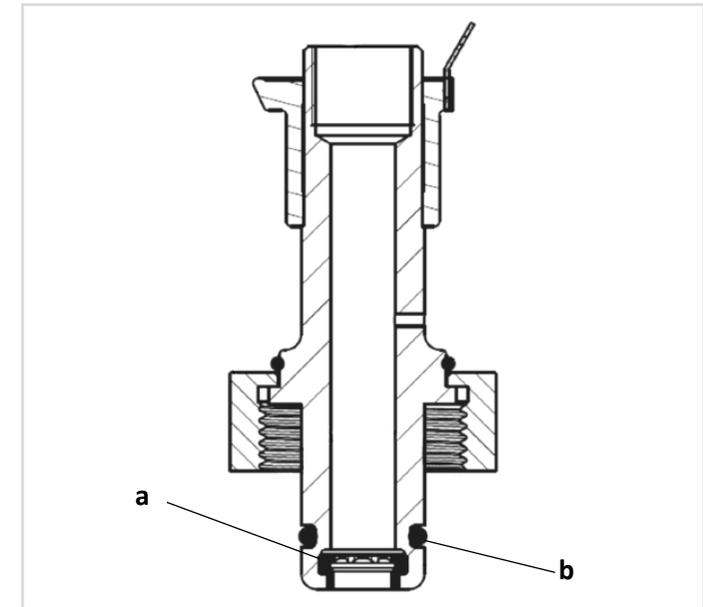
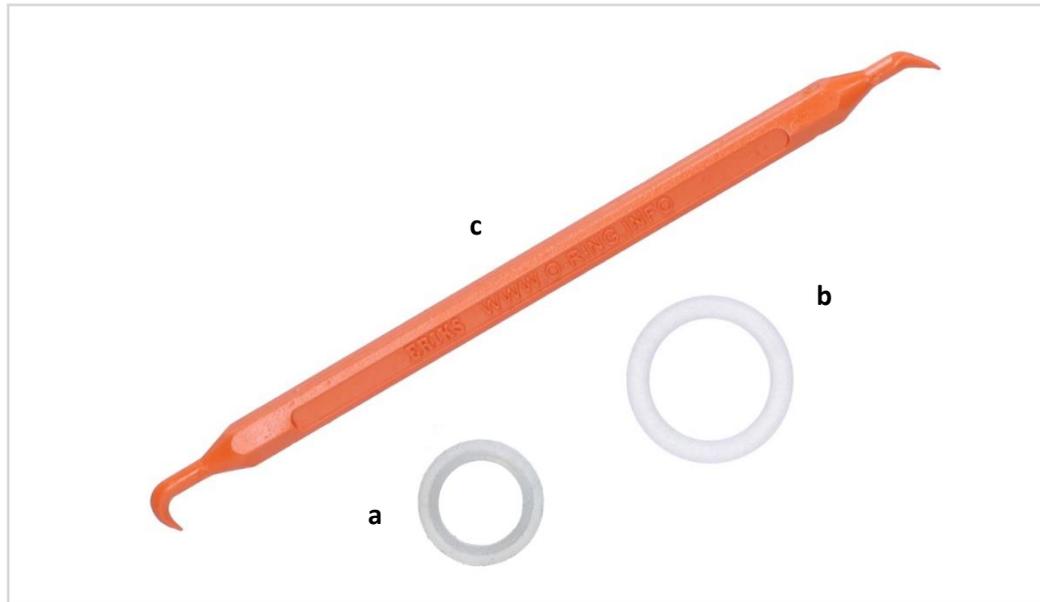


Kit Content	Pcs.	Pos.
Molded gasket OD 17.8 silicone (VMQ)	1	a
O-ring OD 18.64 W 3.53 silicone (VMQ) (only needed for DN25/G1¼")	1	b
O-ring picker	1	c

XPC0017-F+R1: Kit CPA842 wetted sealings EPDM



XPC0017-F+R2: Kit CPA842 wetted sealings FKM

(all process connections)

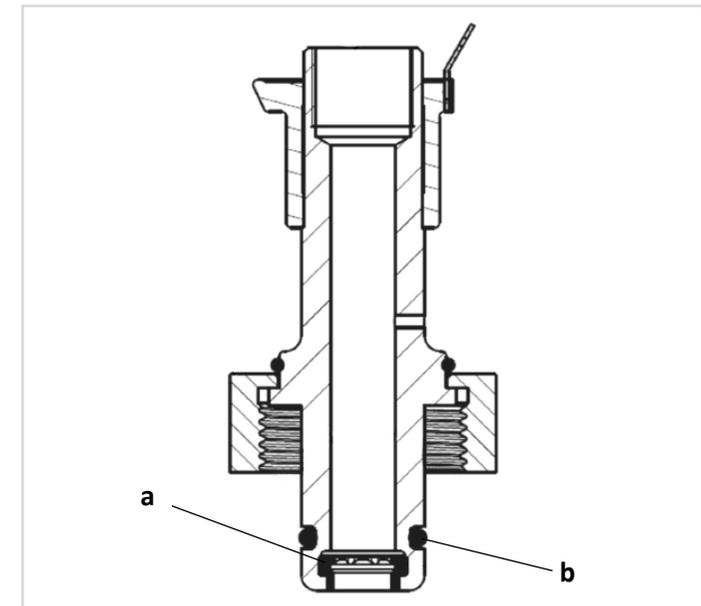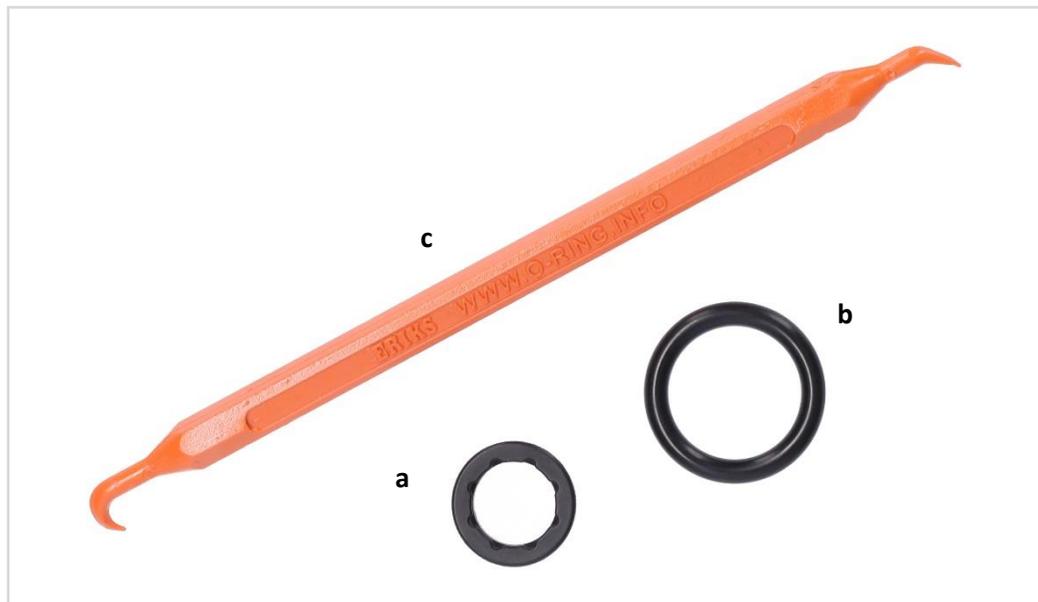



Kit Content	Pcs.	Pos.
Molded gasket OD 17.8 EPDM/ FKM	1	a
O-ring OD 18.66 W 3.53 EPDM (only needed for DN25/G1¼")	1	b
O-ring OD 18.64 W 3.53 FKM (only needed for DN25/G1¼")	1	b
O-ring picker	1	c

XPC0017-F+R3: Kit CPA842 wetted sealings FFKM for process connection DN25 / G 1¼" only (CPA842-+++K1AA/AB++)

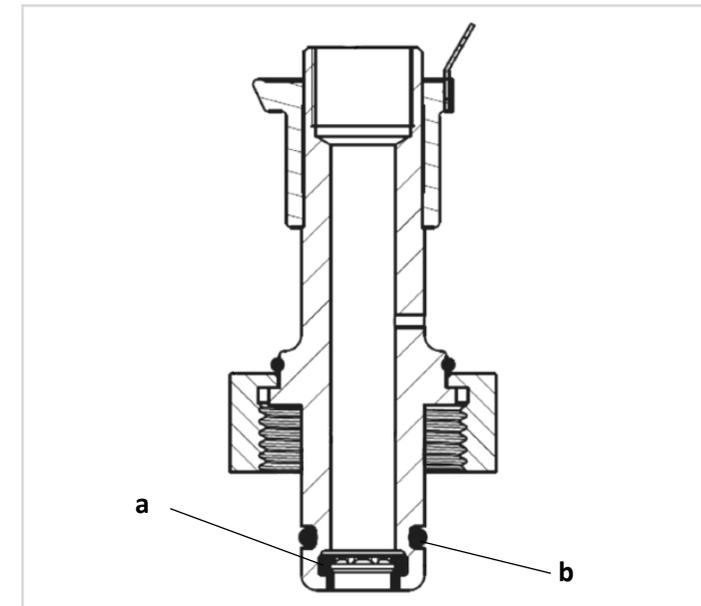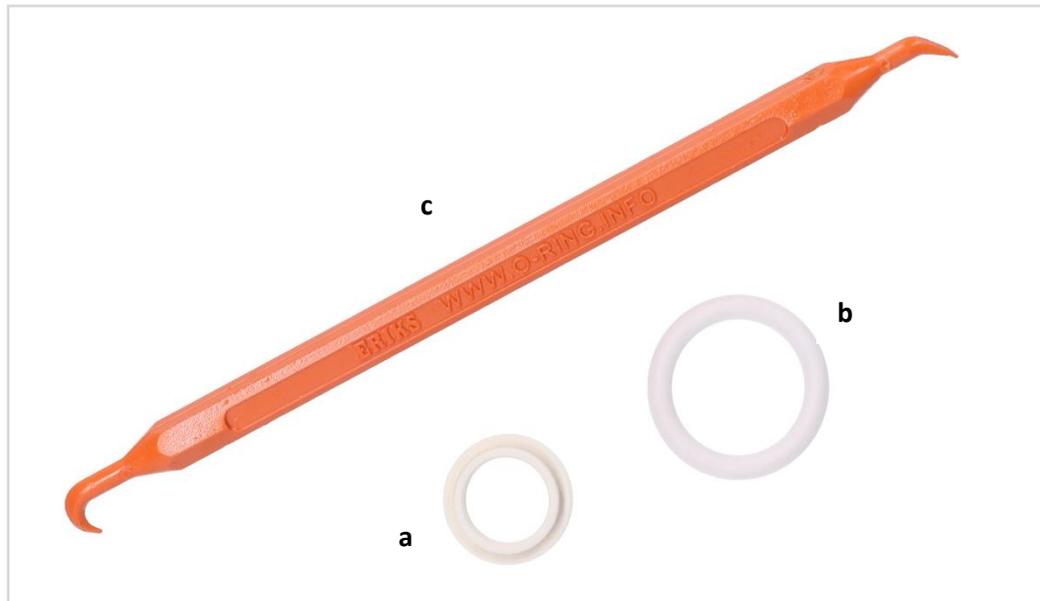



Kit Content	Pcs.	Pos.
Molded gasket OD 17.8 FFKM	1	a
O-ring OD 18.64 W 3.53 FFKM (only needed for DN25/G1¼")	1	b
O-ring picker	1	c

XPC0017-F+R4: Kit CPA842 wetted sealings FFKM for all process connections EXCEPT DN25 / G 1 1/4"

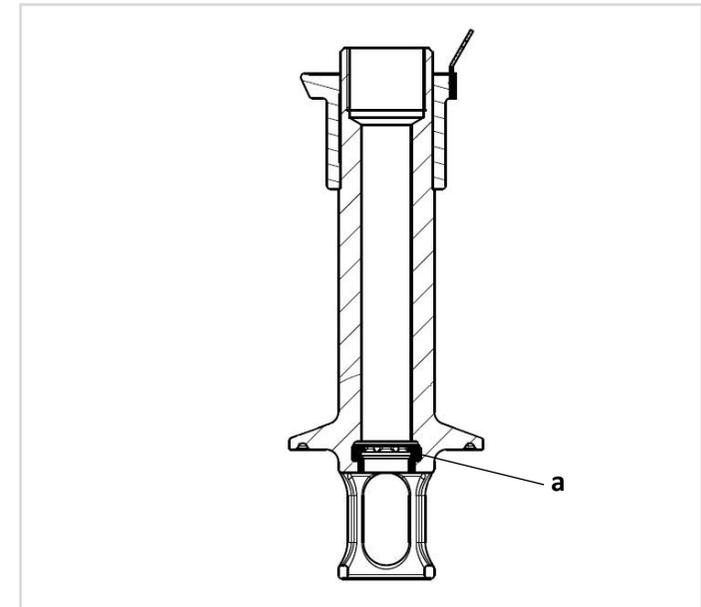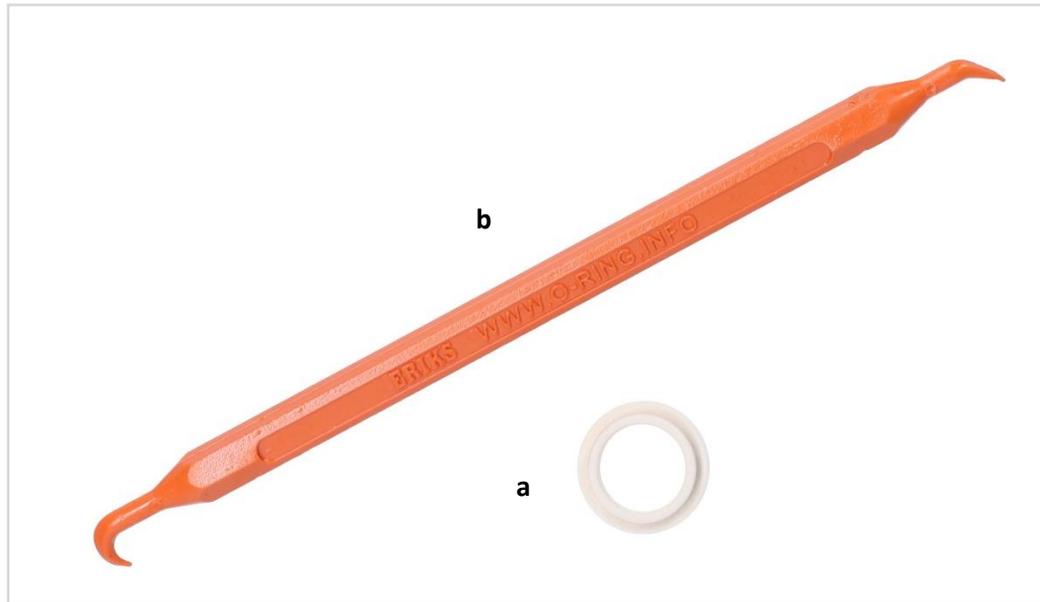


Kit Content	Pcs.	Pos.
Molded gasket OD 17.8 FFKM	1	a
O-ring picker	1	b

XPC0017-F+R5: Kit CPA842 O-rings silicone (VMQ) for assemblies with silicone O-rings and process connection DN25 / G 1¼" (CPA842-xxxS2AA/AB++)

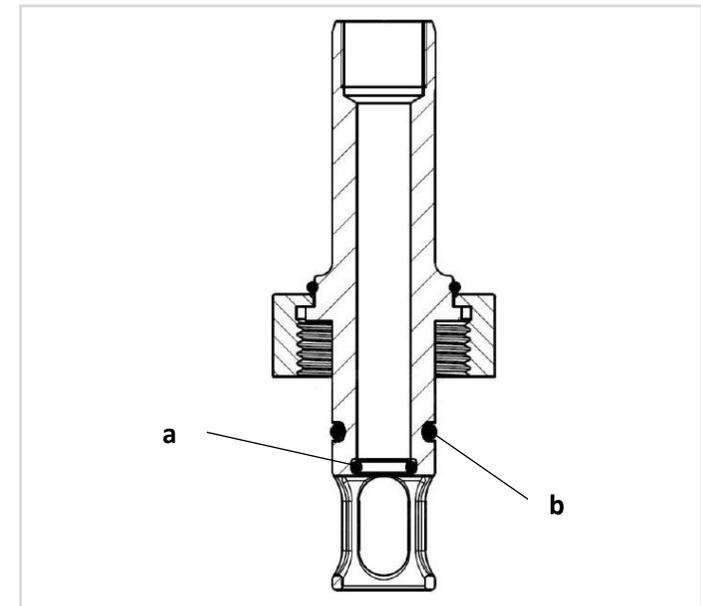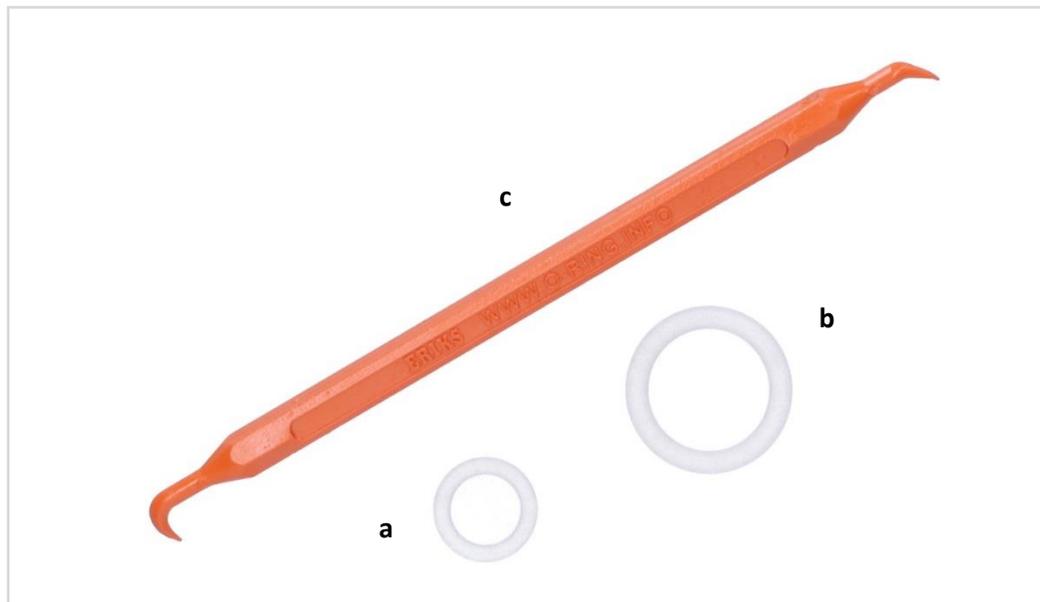



Kit Content	Pcs.	Pos.
O-ring ID 18.64 W 3.53 silicone (VMQ)	1	a
O-ring ID 10.78 W 2.62 silicone (VMQ)	1	b
O-ring picker	1	c

Kit XPC0017-F+R6: Protection cover

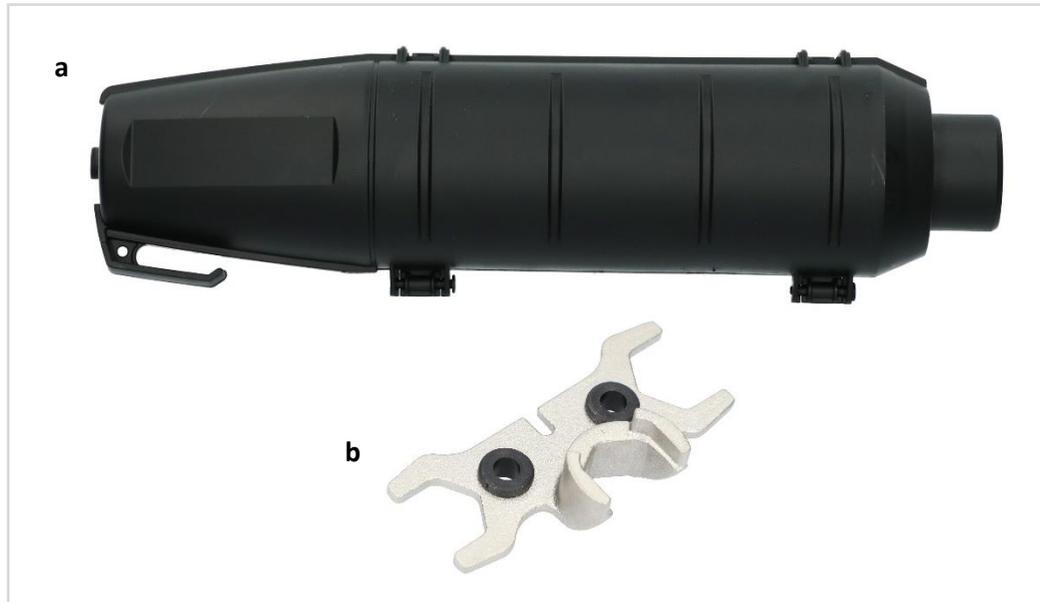

Kit Content	Pcs.	Pos.
Protection cover	1	a
Mounting tool open end wrench AF17-AF19	1	b

XPC0017-F+R7: Kit CPA842 O-rings for blind plug DN25

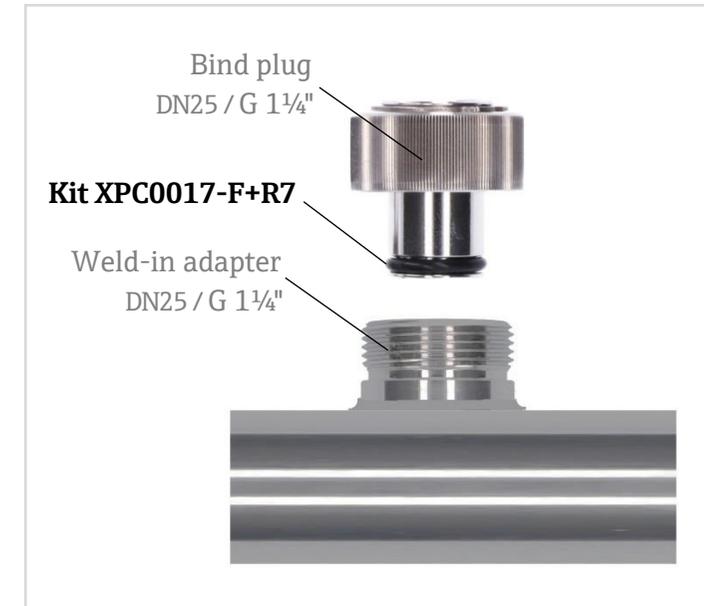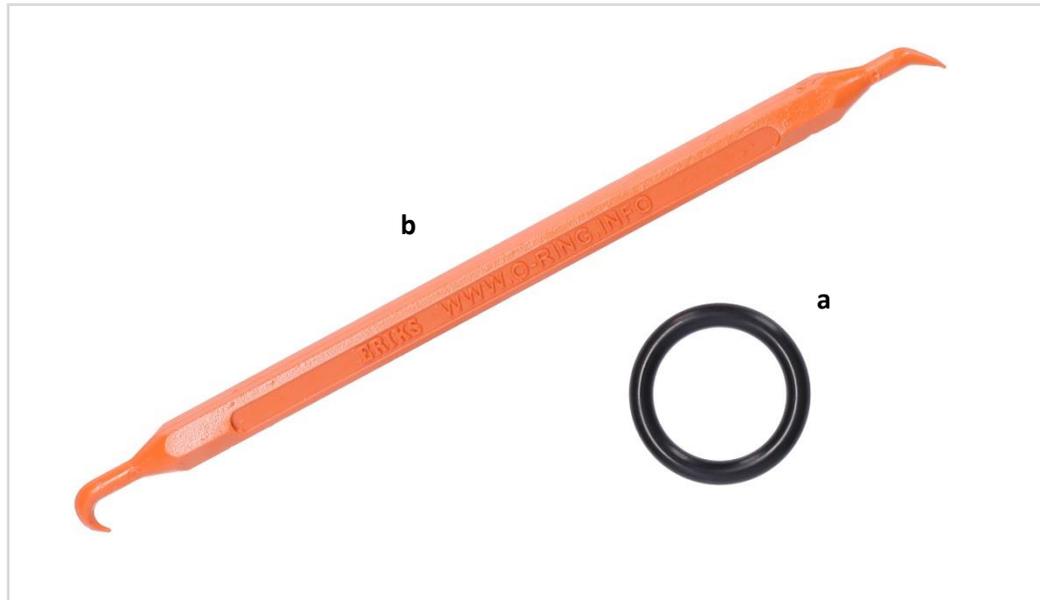

Kit Content	Pcs.	Pos.
O-ring ID 18.64 W 3.35 FKM for blind plug DN25	2	a
O-ring picker	1	b

XPC0017-F+R8: Kit lubricant Klüber Paraliq GTE 703



Kit Content	Pcs.	Pos.
Lubricant Klüber Paraliq GTE 703 (60g)	1	a
Cleaning tissue	1	b