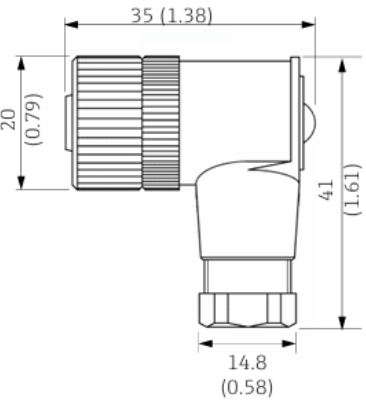


# 71535693 M12 coupling

Accessory	Description
<ul style="list-style-type: none"><li>▪ M12x1 coupling; elbowed, for termination of connecting cable by user</li><li>▪ Connection to M12x1 housing connector</li><li>▪ Body materials PBT/PA,</li><li>▪ Union nut GD-Zn, nickel-plated</li><li>▪ IP67 degree of protection (fully locked)</li><li>▪ Voltage: max. 250 V</li><li>▪ Current carrying capacity: max. 4 A</li><li>▪ Temperature: -40 to +85 °C</li></ul>	 <p>Technical drawing of the M12 coupling showing dimensions in millimeters and inches:</p> <ul style="list-style-type: none"><li>Length: 35 (1.38) mm</li><li>Outer diameter: 20 (0.79) mm</li><li>Height: 41 (1.61) mm</li><li>Width: 14.8 (0.58) mm</li></ul> <p>A0020722</p>