


EA01637T/04/A2/01.25-00
71705953
2025.05.08

TA30S

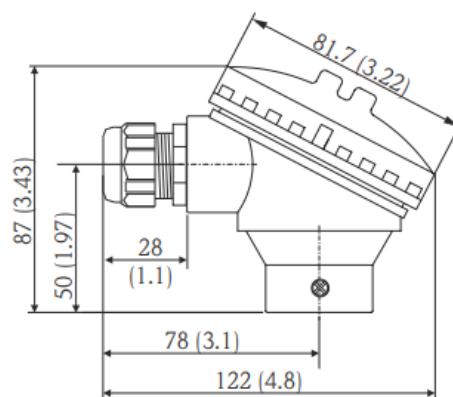

- Schutzart: IP65 (NEMA Type 4x encl.)
- Temperatur: -40 ... +85 °C (-40 ... +185 °F) ohne Kabelverschraubung
- Material: Polypropylen (PP), FDA konform, Dichtungen: O-Ring EPDM
- Kabeleingang Gewinde: $\frac{3}{4}$ " NPT (mit Adapter für $\frac{1}{2}$ " NPT), M20x1.5
- Schutzarmaturanschluss: $\frac{1}{2}$ " NPT
- Farbe: Weiß
- Gewicht: ca. 100 g (3.5 oz)
- Erdungsklemme: nur intern über Hilfsklemme
- Für Klasse II und III Anwendungen nicht erlaubt
- Erhältlich mit 3-A gekennzeichneten Sensoren

- Degree of protection: IP65 (NEMA Type 4x encl.)
- Temperature: -40 to +85 °C (-40 to +185 °F) without cable gland
- Material: polypropylene (PP), FDA-compliant, seals: O-ring EPDM
- Cable entry thread: $\frac{3}{4}$ " NPT (with adapter for $\frac{1}{2}$ " NPT), M20x1.5
- Protective assembly connection: $\frac{1}{2}$ " NPT
- Color: white
- Weight: approx. 100 g (3.5 oz)
- Ground terminal: only internal via auxiliary terminal
- Not allowed for Class II and III applications
- Available with 3-A marked sensors