

XPC0017-F: Kits CPA842 Accessories

Content:

Order code	Spare part	Page
XPC0017-F+M1	Kit CPA842 Weld-in socket G 1¼"/DN25 standard straight, 316L (1.4435)	2
XPC0017-F+M2	Kit CPA842 Weld-in socket G 1¼"/DN25 standard oblique, 316L (1.4435)	3
XPC0017-F+M3	Kit CPA842 Weld-in socket G 1¼"/DN25 B.Braun straight, 316L (1.4435)	4
XPC0017-F+M4	Kit CPA842 Weld-in socket G 1¼"/DN25 B.Braun oblique, 316L (1.4435)	5
XPC0017-F+M5	Kit CPA842 Blind plug G 1¼"/DN25 standard, 316L (1.4404), FKM-FDA	6
XPC0017-F+M6	Kit CPA842 Blind plug G 1¼"/DN25 B.Braun, 316L (1.4404), FKM-FDA	7
XPC0017-F+PQ	Kit CPA842 Dummy sensor 120mm, 316L (1.4404), Ra=0.38	8
XPC0017-F+P1	Kit CPA842 Snap rings for G 1¼"/DN25, 10 pieces	9
XPC0017-F+R6	Kit CPA842 Protection cover for sensor head	10
XPC0017-F+R8	Kit CPA842 Lubricant Klüber Paraliq GTE 703 (60 g)	11
XPC0017-F+RS	Kit Sensor mounting open-end wrenches	12

XPC0017-F+M1: Kit CPA842 Weld-in socket G 1¼"/DN25 standard straight, 316L (1.4435)




Kit Content	Pcs.	Pos.
Weld-in socket straight G 1¼"/DN25, l = 30 mm, 316L (1.4435)	1	a
Cleaning tissue	1	b

XPC0017-F+M2: Kit CPA842 Weld-in socket G 1¼"/DN25 standard oblique, 316L (1.4435)



Kit Content	Pcs.	Pos.
Weld-in socket G 1¼"/DN25 oblique, l = 39 mm, 316L (1.4435), 15°	1	a
Cleaning tissue	1	b

XPC0017-F+M3: Kit CPA842 Weld-in socket G 1¼"/DN25 B.Braun straight, 316L (1.4435)

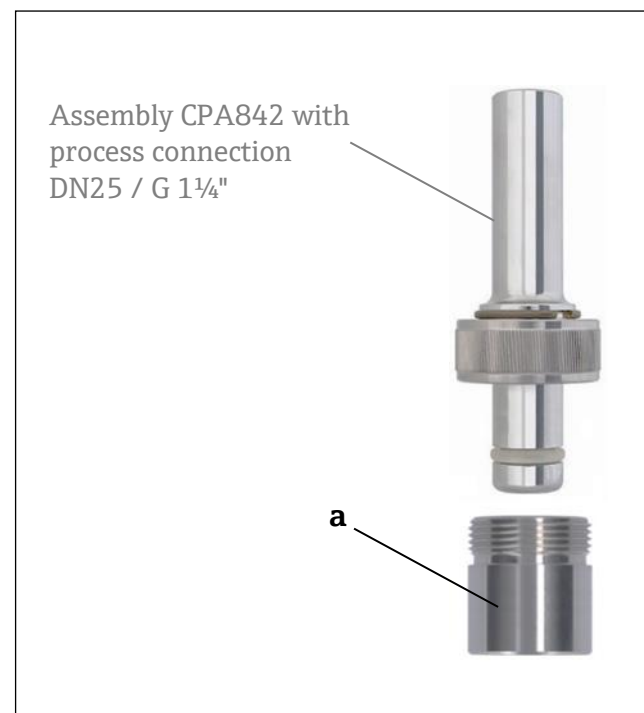

Kit Content	Pcs.	Pos.
Weld-in socket G 1¼"/DN25 straight B.Braun, l = 50 mm (2"), 316L (1.4435)	1	a
Cleaning tissue	1	b

XPC0017-F+M4: Kit CPA842 Weld-in socket G 1¼"/DN25 B.Braun oblique, 316L (1.4435)



Kit Content	Pcs.	Pos.
Weld-in socket G 1¼"/DN25 oblique B.Braun, l = 59 mm (2.3"), 316L (1.4435), 15°	1	a
Cleaning tissue	1	b

XPC0017-F+M5: Kit CPA842 Blind plug G 1¼"/DN25 standard, 316L (1.4404) with sealing FKM-FDA




Kit Content	Pcs.	Pos.
Blind plug G 1¼"/DN25 standard, l = 30 mm, 316L (1.4404), FKM-FDA	1	a
Cleaning tissue	1	b

XPC0017-F+M6: Kit CPA842 Blind plug G 1¼"/DN25 B.Braun, 316L (1.4404) with sealing FKM-FDA




Kit Content	Pcs.	Pos.
Blind plug G 1¼"/DN25 B.Braun, l = 50 mm, 316L (1.4404), FKM-FDA	1	a
Cleaning tissue	1	b

XPC0017-F+PQ: Kit CPA842 Dummy sensor 120mm, 316L (1.4404), Ra=0.38

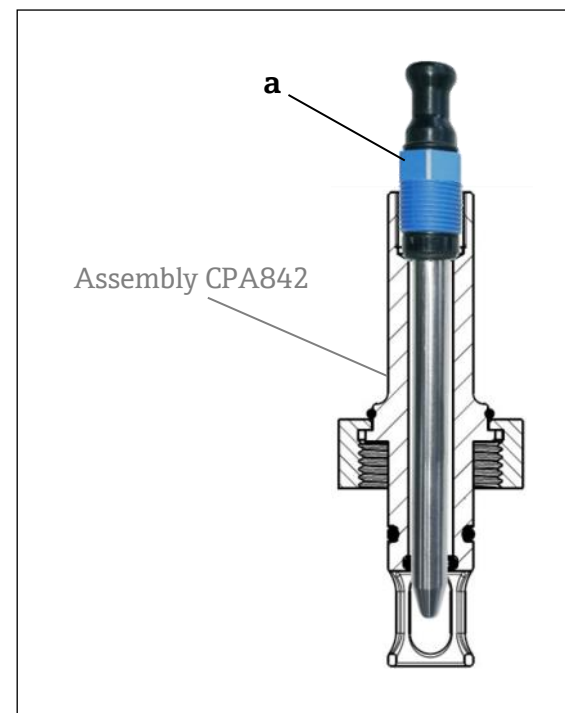


Kit Content	Pcs.	Pos.
Dummy sensor 120 mm, 316L (1.4404), Ra = 0.38	1	a
Cleaning tissue	1	b

XPC0017-F+P1: Kit CPA842 Snap rings for assembly versions G 1¼"/DN25, 10 pieces

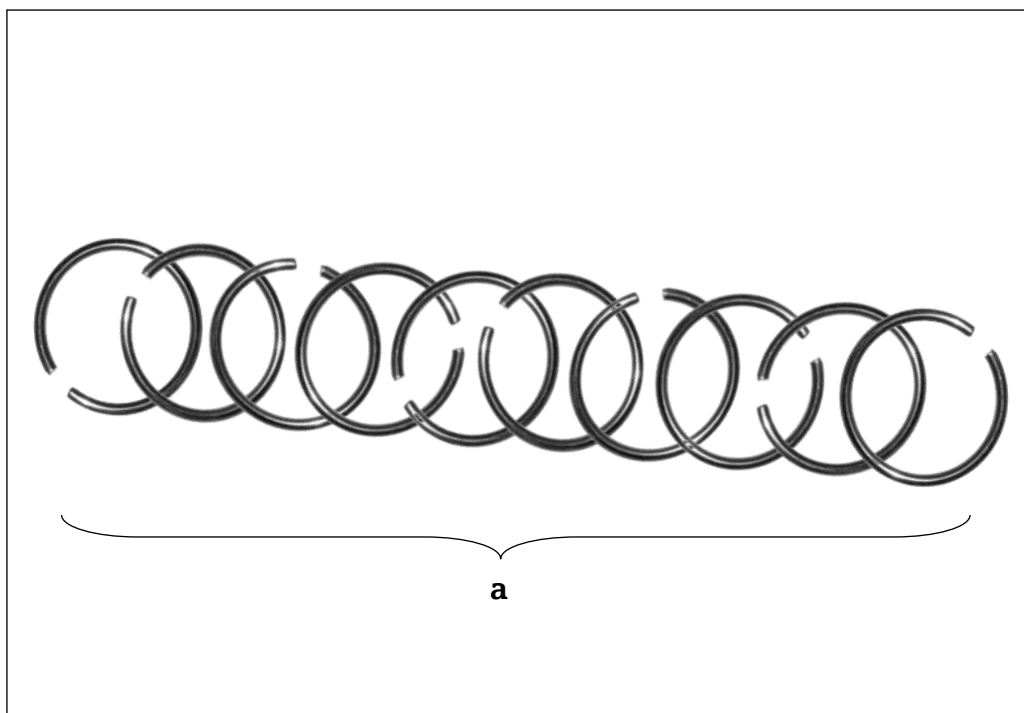

Kit Content	Pcs.	Pos.
Snap ring for G 1¼"/DN25	10	a

XPC0017-F+R6: Kit CPA842 Protection cover for sensor plug head (only for CPA842-xxxxxxx+NC)

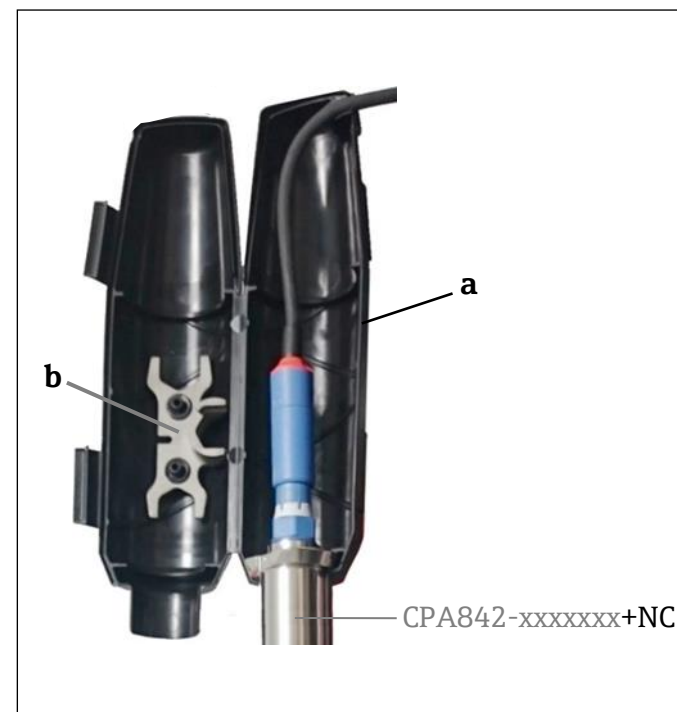


Kit Content	Pcs.	Pos.
Protection cover for sensor plug head	1	a
Mounting tool (open end wrench)	1	b

XPC0017-F+R8: Kit CPA842 Lubricant Klüber Paraliq GTE 703 (60 g)



Kit Content	Pcs.	Pos.
Lubricant Klüber Paraliq GTE 703 (60g)	1	a
Cleaning tissue	1	b

XPC0017-F+RS: Kit Sensor mounting tool

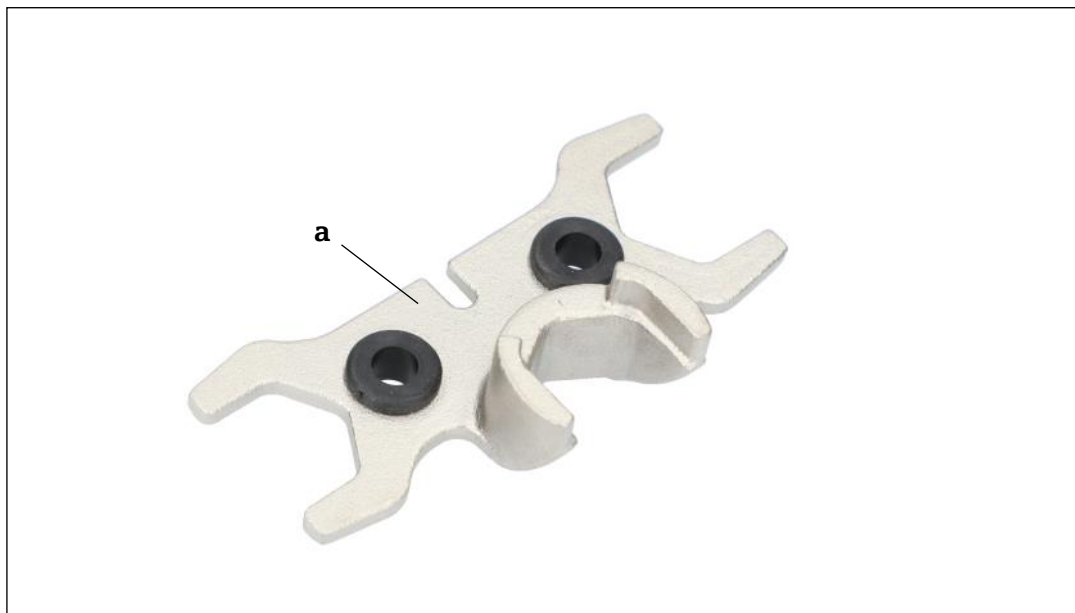

Kit Content	Pcs.	Pos.
Sensor mounting tool (open end wrench) AF17 + 19 mm	2	a