


EA01635T/04/A2/01.25-00
71705950
2025.05.08

TA30P

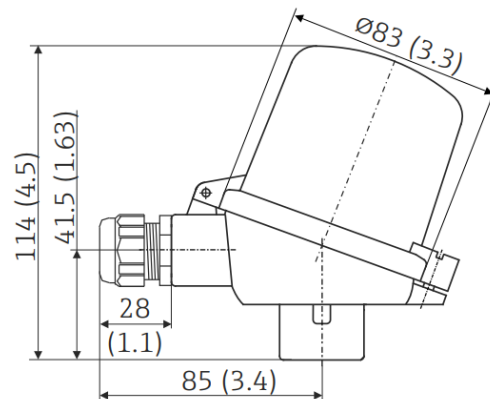

- Schutzart: IP65
- Max. Temperatur: -40 ... +120 °C (-40 ... +248 °F)
- Material: Polyamid (PA12), antistatisch
Dichtungen: Silikon
- Kabeleingang Gewinde: M20x1,5
- Schutzarmaturanschluss: M24x1,5
- Es können zwei Kopftransmitter montiert werden. Standardmäßig ist ein Transmitter, montiert im Anschlusskopfdeckel, sowie ein zusätzlicher Anschlussklemmenblock direkt am Messeinsatz installiert.
- Kopf- und Kappenfarbe: schwarz
- Gewicht: 135 g (4,8 oz)
- Zündschutzart: Eigensicher (G Ex ia)
- Erdungsklemme: nur intern über Hilfsklemme
- Erhältlich mit 3-A® gekennzeichneten Sensoren

- Degree of protection: IP65
- Max. temperature: -40 to +120 °C (-40 to +248 °F)
- Material: polyamide (PA12), antistatic
Seals: silicone
- Threaded cable entry: M20x1.5
- Protective fitting connection: M24x1.5
- Two head transmitters can be mounted. In the standard configuration one transmitter is mounted in the terminal head cover and an additional terminal block is installed directly on the insert.
- Head and cap color: black
- Weight: 135 g (4.8 oz)
- Type of protection: intrinsic safety (G Ex ia)
- Ground terminal: only internal via auxiliary terminal
- Available with sensors with 3-A® symbol