

编号:

Number 2023-3371

设备名称: 蓝牙设备
Equipment Name

设备型号: Picomag
Equipment Type

主要功能: 数据传输
Main Functions

调制方式: GFSK
Modulation Mode

主要技术参数及其指标值:
Main Technical Parameters


频率范围: 2400-2483.5MHz
Frequency Range

频率容限: $\leq 20\text{ppm}$
Frequency Tolerance

占用带宽: $\leq 3\text{MHz}$
Occupied Bandwidth

发射功率: $\leq 20\text{dBm (EIRP)}$
Transmitting Power

杂散发射限值: $\leq -30\text{dBm}$
Spurious Emission Limits

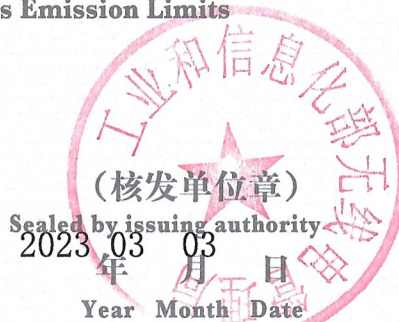

无线电发射设备
Radio Transmission Equipment
型号核准证
Type Approval Certificate

瑞士 Endress+Hauser Flowtec AG:

根据《中华人民共和国无线电管理条例》
In accordance with the provisions on the Radio
Regulations of the People's Republic of China , the following
符合中华人民共和国无线电管理规定和
radio transmission equipment , after examination , conforms
技术标准，其核准代码为： CMIIT ID:2018DJ2288
to the provisions with its CMIIT ID:

有效期： 2025-12-31
Validity



Sealed by issuing authority
2023 03 03 日
Year Month Date