

Safety Instructions

Levelflex FMP54/56/57

4-20 mA HART

Associated Safety Instructions (XA) on page 4



Levelflex FMP54/56/57

4-20 mA HART

Table of contents

Associated documentation 4

Zone 20: Compact; Remote; 1 channel 5

Zone 20: Compact; Remote; 2 channels 5

Associated documentation


This document is an integral part of the following Safety Instructions:

ATEX, IECEx:
XA00541F/00

UK:
XA02537F/00

**Zone 20: Compact; Remote;
1 channel**

Probe design: compact; remote
Position 3 = A, B, C: 1 channel used

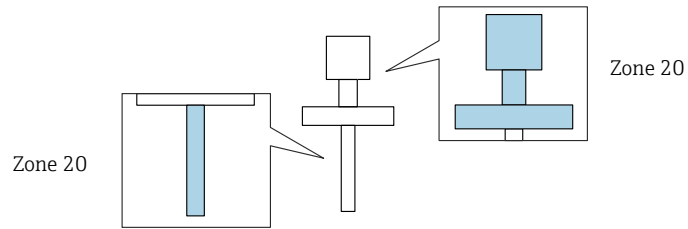


FMP5x

	(1)			
	A, B, C	$T = T_a + 5 \text{ K}$ $T_{200} = T_a + 21 \text{ K}$	$T_a = 80$ $T_a = 64$	85

**Zone 20: Compact; Remote;
2 channels**

Probe design: compact; remote
Position 3 = B, C: 2 channels used

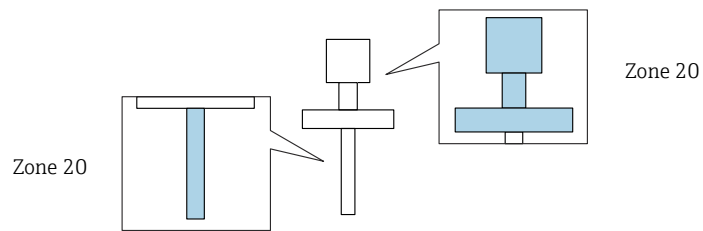

FMP5x

	(2)			
	B, C	$T = T_a + 10 \text{ K}$ $T_{200} = T_a + 42 \text{ K}$	$T_a = 75$ $T_a = 43$	85



71531283

www.addresses.endress.com
