




KA00094F/00/A6/13.15  
71297880

**Minicap**  
**FTC260**



- DE** Sicherheitsschaltung
- EN** Fail-safe mode
- FR** Mode de sécurité
- ES** Modo de seguridad
- IT** Modalità di sicurezza
- NL** Veiligheidsschakeling

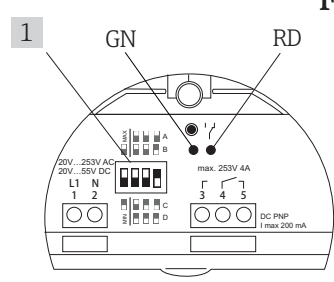

1		GN	RD	U = DC	
MAX					
MIN					



<b>A</b>	1			N: $\epsilon_r > 1.6$ M: ---
<b>B</b>	1 Factory settings			N: $\epsilon_r > 2.0$ M: $\epsilon_r > 1.6$
<b>C</b>	1			N: $\epsilon_r > 2.5$ M: $\epsilon_r > 2.0$
<b>D</b>	1			N: $\epsilon_r > 3.5$ M: $\epsilon_r > 2.5$

<b>DE</b>	Behälter:	M = metallisch	N = nichtmetallisch
<b>EN</b>	Vessel:	M = metallic	N = non-metallic
<b>FR</b>	Réservoir:	M = métallique	N = non métallique
<b>ES</b>	Depósito:	M = metálico	N = non metálico
<b>IT</b>	Serbatoio:	M = metallico	N = non metallico
<b>NL</b>	Tank:	M = metaal	N = geen metaal

<b>DE</b>	B = Werkeinstellung
<b>EN</b>	B = Factory settings
<b>FR</b>	B = Réglages usine
<b>ES</b>	B = Ajustes de fábrica
<b>IT</b>	B = Impostazione di fabbrica
<b>NL</b>	B = Fabrieksinstelling

KA00094F/00/A6/13.15  
71297880



71297880